





EN Operating instructions. page 1
Original


AZ/AZM201...ST-...-2965-1 (MS-AZ/AZM 200ST-...-2568)

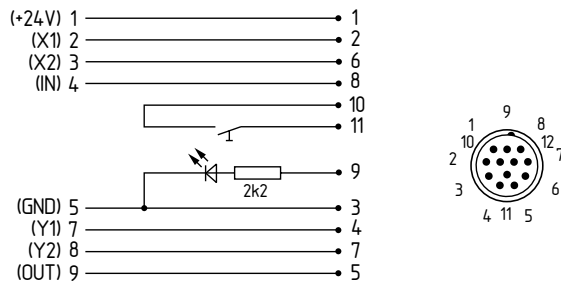


AZ/AZM201...ST-/ST2-...-2965-2 (MS-AZ/AZM 200ST-...-2562)

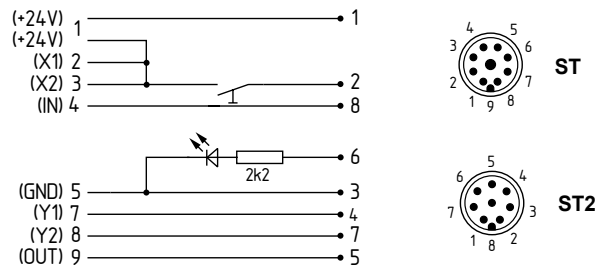


AZ/AZM201...ST-...-2965-3 (MS-AZ/AZM 200ST-...-2591)

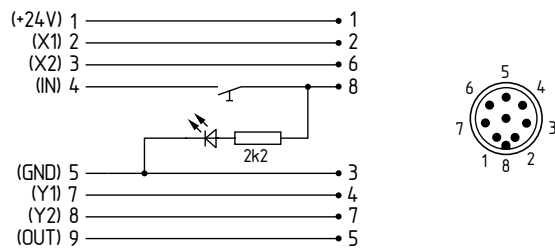


AZ/AZM201...ST-...-2965-4 (MS-AZ/AZM 200ST-...-2561-1)

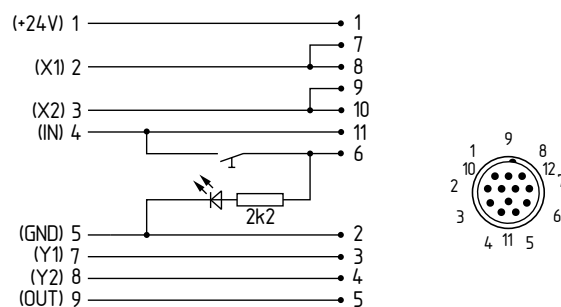

AZ/AZM201...ST-...-2965-5 (MS-AZ/AZM 200ST-...-2561-2)

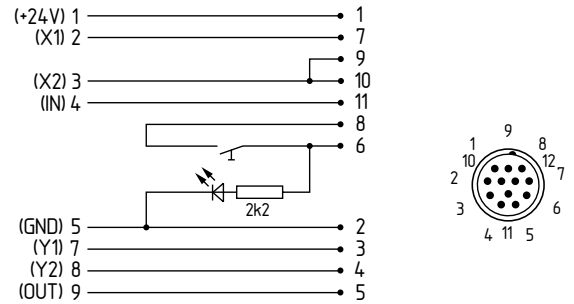

AZ/AZM201...ST-...-2965-6

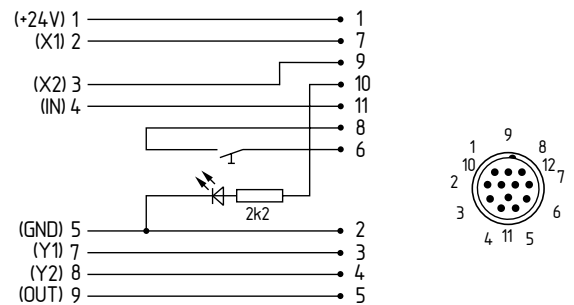

Pre-wired cables for AZ/AZM201...ST-...-2965-1/ -4/ -5/ -6

with female connector IP67, M23, 12-pole – 12 x 0.75 mm²

Cable length	Ordering code
5.0 m	101208520
10.0 m	103007354
20.0 m	101214418

Pre-wired cables for AZ/AZM201...ST-...-2965-2

with female connector IP67, M23, 8+1-pole – 8 x 0.75 mm²

Cable length	Ordering code
5.0 m	101209959
10.0 m	101209958
15.0 m	103001384

Pre-wired cables for AZ/AZM201...ST-...-2965-3

Pre-wired cables for AZ/AZM201...ST2-...-2965-2

with female connector IP67, M12, 8-pole – 8 x 0.25 mm²

Cable length	Ordering code
2.5 m	103011415
5.0 m	103007358
10.0 m	103007359



Cable and device fuse rating: internal short-circuit proof

- Connector M12: ≤ 2 A gG
- Connector M23: ≤ 3 A gG
- Ambient temperature: max. 60°C

K.A. Schmersal GmbH & Co. KG

Mödinghofe 30, 42279 Wuppertal
Germany

Phone: +49 202 6474-0

Telefax: +49 202 6474-100

E-Mail: info@schmersal.com

Internet: www.schmersal.com

